




2470-1112 Combo-D Filtered Plug Connector

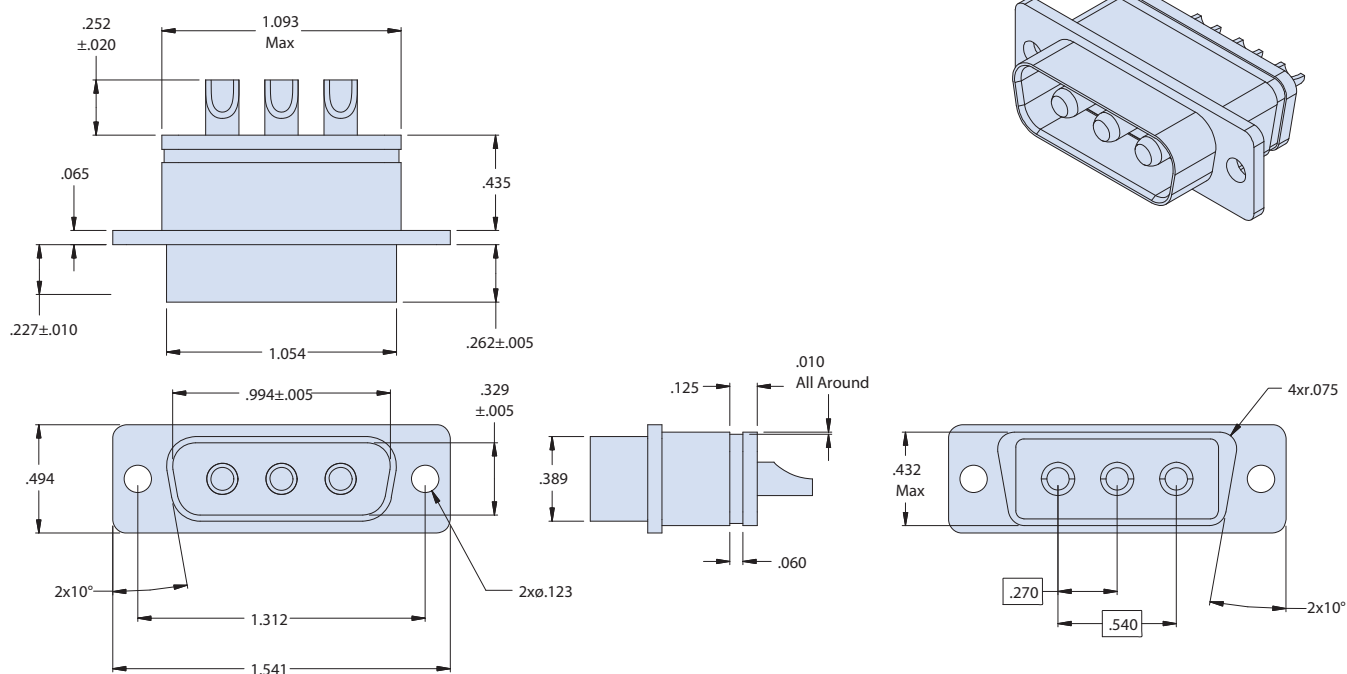

Notes

1. Assembly to be identified with Glenair's name, part number, and date code space permitting
2. Electrical Performance: C filter
Capacitance: 80 – 120 nF
Dielectric Withstanding Voltage: 500 VDC
Insulation Resistance: 5,000 Megohms @ 200 VDC

Materials/Finishes:

Shell - Aluminum/Yellow Chromate over Cadmium (JF)
Insulators - High Grade Rigid Dielectric / NA
Contacts - Copper Alloy / Gold Plated
Hardware - Stainless Steel/Passivated
Interfacial Seal - Fluorosilicone Blend / NA

Dimensions in inches (millimeters) and are subject to change without notice.

© 2013 Glenair, Inc.

U.S. CAGE Code 06324

Printed in U.S.A.