


SERIES 28 HiPer-D Combo Connectors

The Combo *Hi-Performance* D-Sub connector combines size #8 power or RF contacts with size #20 signal pins. The HiPer-D® meets the need for improved performance in hostile environments. Unlike standard M24308 connectors with stamped steel shells, the HiPer-D® connector features a one-piece machined aluminum shell. The thermoset epoxy insulators are capable of 200°C continuous operating temperature. Aerospace grade fluorosilicone grommets and face seals provide environmental protection.

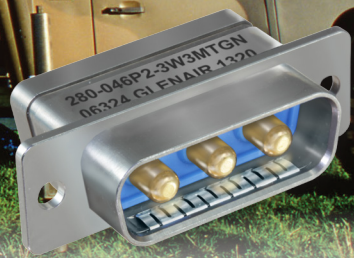

Product Features

- Size #8 Contacts
- 20 Contact Arrangements
- Closed Entry Insulator Protects Socket Contacts
- EMI Protection
- High Temperature Thermoset Epoxy Insulators
- Watertight Sealing
- Rugged Machined One-Piece Shell

