

HIGH-VOLTAGE kV Seal Contact Assemblies



For high-voltage DC utility applications
Selection Guide

INTRODUCTION

GHV-001

kV Seal Size #12 contacts



GHV-001 kV Seal Size #12 13.5 kV contacts for Glenair SuperNine and D38999 Series I, III, and IV connectors
page 4

GHV-002

kV Seal Plus Size #12 contacts



GHV-002 kV Seal Plus Size #12 15 kV contacts for Glenair SuperNine and D38999 Series I, III, and IV connectors
page 5

GHV-003

kV Seal Size #12 contacts



GHV-003 kV Seal Size #12 13.5 kV contacts for Glenair Mighty Mouse and Series 79, and D38999 Series II connectors
page 6

GHV-004

kV Seal Size #8 contacts



GHV-004 kV Seal Size #8 22 kV contacts for Size #8 cavities in SuperNine, Mighty Mouse Series 801, 802, 805, and Series 79 rectangular connectors
page 7


CONNECTOR COMPATIBILITY, CONTACT SIZES AND VOLTAGE RATINGS

Size #12 contacts accommodate #22 or #24 AWG conductors and are rated for operating voltages from 13.5 kVDC to 15 kVDC. Size #8 contacts utilize #16 AWG conductors and support operating voltages to 22 kVDC.


- SuperNine and D38999 Series I, II, III, and IV
- Mighty Mouse Series 801, 802, and 805
- Series 79 Micro-Crimp




Directional Radar

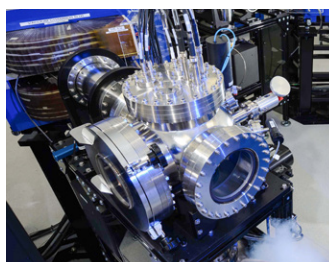

Mass Spectrometers

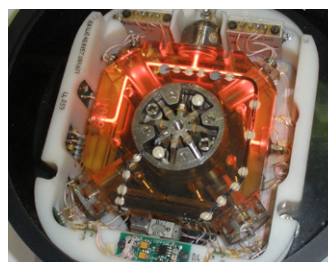

Ring Laser Gyroscopes

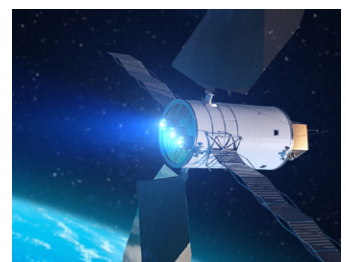

Electric Propulsion