




SERIES 80 MIGHTY MOUSE CONNECTORS Accessories, Backshells, and Tools



Product Selection Guide

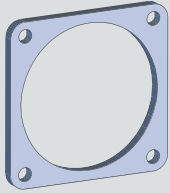

Flange Gaskets

Die-cut flange gaskets provide panel sealing for flange mount receptacles. Available in fluorosilicone, Viton®, and conductive fluorosilicone.

Page N-2



Heat-Shrink Boots

These boots provide strain relief, environmental protection and fit all Series 80 connectors. Straight, 90°, 45°, Long Tail, and USB versions.

Page N-39



O-rings

Replace lost or damaged O-rings. Available in fluorosilicone, EPDM, and conductive fluorosilicone, these O-rings fit Mighty Mouse jam nut receptacles.

Page N-5



Connector Holding Tools and Band-Master ATS Banding Tool

Connector holding tools for tightening backshells and Band-Master ATS shield termination systems.

Page N-46



Mounting Flange

Replace worn or lost mounting flanges. Offered with standard or metric threads.

Page N-10



Series 800 thru 805 Protective Covers

Thread-on or frictions fit covers provide a watertight seal and prevent damage. Select nylon cord or wire rope lanyards with a range of ring terminal diameters to fit just about any need.

Page N-48



Jam Nuts, Hex Nuts and Spanner Wrench Sockets

Mighty Mouse jam-nut receptacles are supplied with low-profile spanner nuts. Jam-nuts require the use of a spanner wrench socket to be tightened. Optional hex nuts are available with safety wire holes.

Page N-11



Series 800, 801, 804, and 805 Pro-Seal Protective Covers

Lightweight thread-on or pressure-seal covers provide environmental seal and immersion resistance.

Page N-79



Series 800 thru 805 Shorting Caps and Backshells

Backshells feature rotatable or direct coupling saddle clamps to provide strain relief for wire bundles. Upgrade to environmental and EMI protection. Shorting Caps, band and shrink boot adapters also available.

Page N-17



Series 800 Dummy Storage Receptacles

Provide a safe and secure location for cable plugs that are disconnected due to maintenance or repair.

Page N-88