



600HH005
Connector Holding Tool
MIL-DTL-38999 Series IV
Plug and Receptacle

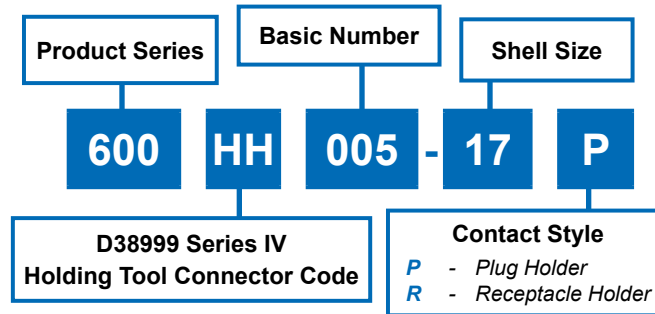

NO POLARIZATION REQUIRED

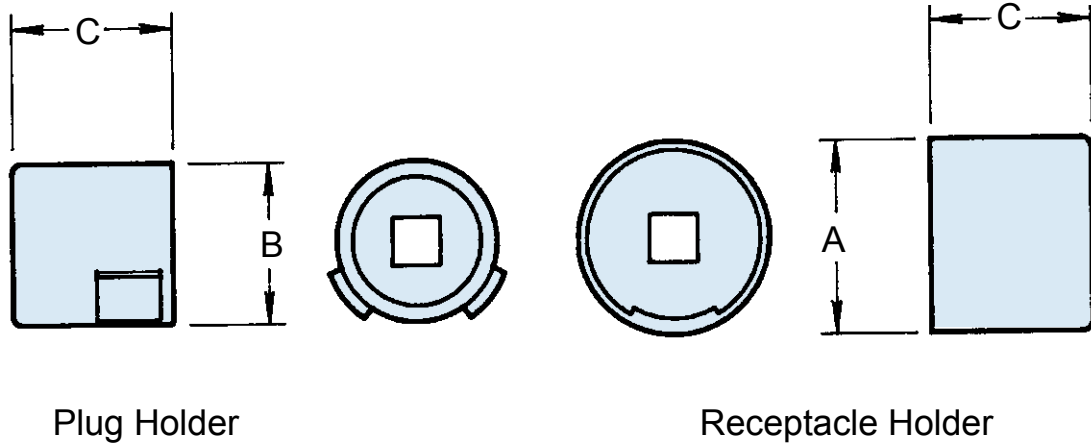

Shell Size		Max. Recommended Torque (Inch Pounds)	A Dia. Max.		B Dia. Max.		C Dim. Max.	
Com'l	Mil. Ref.							
11	B	80	.83	(21.1)	.515	(13.1)	1.28	(32.5)
13	C	110	.95	(24.1)	.650	(16.5)	1.28	(32.5)
15	D	120	1.07	(27.2)	.775	(19.7)	1.28	(32.5)
17	E	120	1.20	(30.5)	.901	(22.9)	1.28	(32.5)
19	F	120	1.28	(32.5)	1.015	(25.8)	1.28	(32.5)
21	G	140	1.40	(35.6)	1.140	(29.0)	1.28	(32.5)
23	H	140	1.53	(38.9)	1.265	(32.1)	1.28	(32.5)
25	J	140	1.66	(42.2)	1.392	(35.4)	1.28	(32.5)

NOTES

1. Metric dimensions (mm) are indicated in parentheses.
2. Material: Case hardened carbon steel with electroless nickel finish.
3. Receptacle and plug holder drives: 1/4" - Shell sizes 11 and 13; 3/8" - Shell sizes 15 and up.