

D-Subminiature

289-008

Banding Backshell, HiPer-D

- Solid Backshell
- Banding Shield Termination
- Environmental



T Top Entry




S Side Entry

Lightweight, one piece, banding. 289-008 backshell fits M24308 D-Subminiature and Series 28 HiPer-D connectors. Internal gasket provides environmental protection when used with Series 28 connector and boot. Heatshrink boot groove accepts lipped Series 77 lipped boots. Terminate cable shield to backshell with .24" wide banding strap. Available in top or side entry. Aluminum with passivated stainless steel screwlocks and clips. Fluorosilicone gasket.

289-008

This accessory fits HiPer-D and D-Subminiature M24308 connectors.



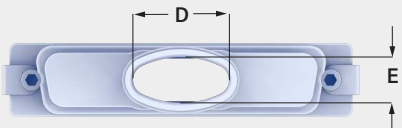

TABLE 1
ENTRY SIZE



Shell Size	Entry Size	D		E	
		in	mm	in	mm
1	A	.143	3.6	.143	3.6
	B	.195	5.0	.195	5.0
	C	.242	6.2	.242	6.2
	D	.438	11.1	.375	9.5
	E	.638	16.2	.375	9.5
2	A	.188	4.8	.188	4.8
	B	.256	6.5	.256	6.5
	C	.480	12.2	.375	9.5
	D	.688	17.5	.375	9.5
	E	.969	24.6	.375	9.5
3	A	.245	6.2	.245	6.2
	B	.550	14.0	.375	9.5
	C	.780	19.8	.375	9.5
	D	1.125	28.6	.375	9.5
	E	1.484	37.7	.375	9.5
4	A	.291	7.4	.291	7.4
	B	.800	20.3	.375	9.5
	C	1.260	32.0	.375	9.5
	D	1.813	46.1	.375	9.5
	E	2.155	54.7	.375	9.5
5	A	.326	8.3	.326	8.3
	B	.770	19.6	.485	12.3
	C	1.250	31.8	.485	12.3
	D	1.750	44.5	.485	12.3
	E	2.031	51.6	.485	12.3
6	A	.376	9.6	.376	9.6
	B	.863	21.9	.550	14.0
	C	1.323	33.6	.550	14.0
	D	1.875	47.6	.550	14.0
	E	2.165	55.0	.550	14.0

PART NUMBER

Sample PN → **289T008 ME 3 A -T S K**

Base P/N	289T008 T Top Entry 289S008 S Side Entry
Finish	TZ Tin-Zinc MN Mega-Nickel JF Cadmium, Yel. Chromate ME Electroless Nickel NF Olive Drab Cadmium MT Nickel-PTFE ZR Black Zinc-Nickel
Shell Size	1 2 3 4 5 6
Entry Size	A B C D E See Table 1
Qwik-Ty	N No Qwik-Ty Strain Relief Arm T Qwik-Ty Arm Included 
Slots	N No Slots S Slots in Banding Area 
Band	N No Band K Standard Band Included J Slim Standard Band Included
Entry Direction	<i>Applies to 289S008 Side Entry Omit for 289T008 Top Entry</i> 1 Direction 1  2 Direction 2  Direction 1 Direction 2
Screwlocks	Omit Socket Head Male Screwlocks T Extended Slot Head Male Screwlocks <i>Entry Sizes ABCD only</i> W Socket Head Male Screwlocks with Safety Wire Holes N Through Holes, No Screwlocks

D-SUBMINIATURE ACCESSORIES