

D-Subminiature

550-102

Shrouded Backshell, Qwik-Ty®

- Split Backshell
- For Unshielded Cable
- Qwik-Ty® Strain Relief



550-102

This accessory fits D-Subminiature M24308 connectors.
Not compatible with Series 28 HiPer-D

Qwik-Ty strain relief, split, shrouded. 550-102 diecast aluminum backshell fits M24308 D-Subminiature connectors. Attach cable tie to Qwik-Ty arm for strain relief. Connector is captivated between backshell halves. Eleven shroud lengths to accommodate mating connector mounting dimensions. #4-40 screwlocks are included. Aluminum with stainless steel screws and washers.

PART NUMBER

		Sample PN →					
Base P/N	Base Part No.	550T102	M	2	R4	H	
	Profile	T					
	Shell Sizes	1-6					
		550E102	E				
		550S102	S				
Finish	TZ	Tin-Zinc					
	MN	Mega-Nickel					
	JF	Cadmium, Yel. Chromate					
	M	Electroless Nickel					
	NF	Olive Drab Cadmium					
	MT	Nickel-PTFE					
	ZR	Black Zinc-Nickel					
Shell Size		1	2	3	4	5	6
Shroud Length	Mating Connector Rear Panel Mounting						
	Code	Panel Thickness	E				
	R1	.031 (0.8)	.247 (6.3)				
	R2	.047 (1.2)	.231 (5.9)				
	R3	.062 (1.6)	.216 (5.5)				
	R4	.093 (2.4)	.185 (4.7)				
	R5	.104 (2.6)	.174 (4.4)				
	R6	.125 (3.2)	.153 (3.9)				
	R7	.156 (4.0)	.125 (3.2)				
	R8	.138 (3.5)	.140 (3.6)				
	R9	.188 (4.8)	.094 (2.4)				
	CC	Cable-to-Cable	.170-.172 (4.3-4.4)				
	F0	Front Panel Mount	.340-.344 (8.6-8.7)				
	Screwlocks (Table 1)	Code	Type	Profiles			
A		Male, Socket Head	S T				
B		Male, Fillister Head	S T				
E		Male, Extended Slotted	S T				
H		Male, Hex Head, Drilled	S T				
J		Male, Slotted, Knurled	E				
K		Male, Slotted, Knurled	S T				
P		Female Hex Post, Fixed	S T				


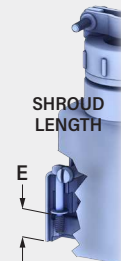


TABLE 1 SCREWLOCK OPTIONS

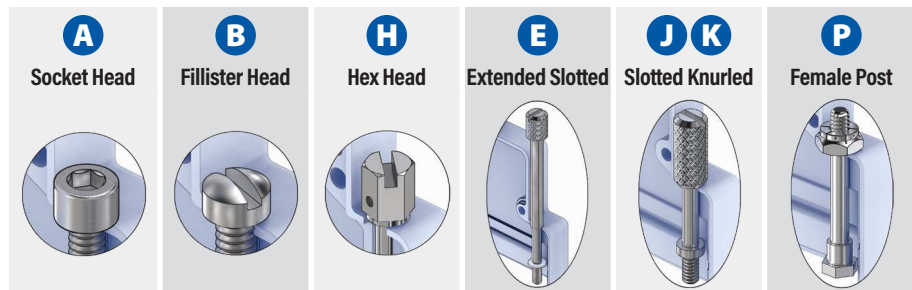

D-SUBMINIATURE ACCESSORIES