

D-Subminiature

550-200

Shorting Cap Backshell, Shrouded




550-200

This accessory fits D-Subminiature M24308 connectors.
Not compatible with Series 28 HiPer-D

Split, shrouded. 550-200 shorting cap fits M24308 D-Subminiature connectors. Two piece backshell has overlapping lip for EMI shielding. Install optional EMI gasket on mating connector panel. Connector is captivated between backshell halves. Eleven shroud lengths to accommodate mating connector mounting dimensions. #4-40 screwlocks are included. Aluminum with stainless steel screws and washers.

TABLE 1
SCREWLOCK OPTIONS

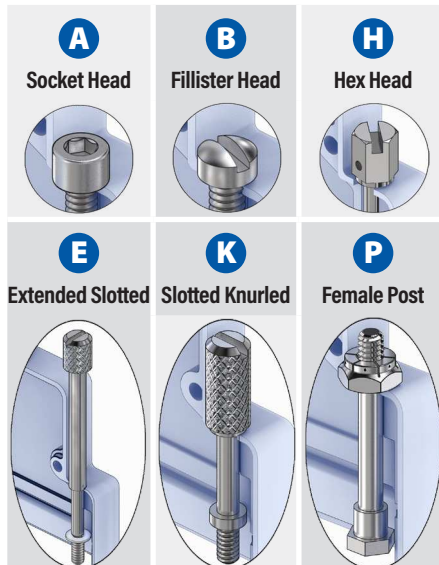

PART NUMBER

Sample PN → **550-200 NF 4 R3 K 0 U 6 -06**

Base P/N	550-200
Finish	<ul style="list-style-type: none"> TZ Tin-Zinc MN Mega-Nickel JF Cadmium, Yel. Chromate M Electroless Nickel NF Olive Drab Cadmium MT Nickel-PTFE ZR Black Zinc-Nickel
Shell Size	1 2 3 4 5 6
Shroud Length	Mating Connector Rear Panel Mounting Panel
	Code Thickness E
	R1 .031 (0.8) .247 (6.3)
	R2 .047 (1.2) .231 (5.9)
	R3 .062 (1.6) .216 (5.5)
	R4 .093 (2.4) .185 (4.7)
	R5 .104 (2.6) .174 (4.4)
	R6 .125 (3.2) .153 (3.9)
	R7 .156 (4.0) .125 (3.2)
	R8 .135 (3.4) .140 (3.6)
	R9 .188 (4.8) .094 (2.4)
CC Cable-to-Cable .174 (4.4)	
F0 Front Panel Mtng. .343 (8.7)	
Screwlocks <i>(Table 1)</i>	A Male, Socket Head
	B Male, Fillister Head
	E Male, Extended Slotted
	H Male, Hex Head, Drilled
	K Male, Slotted, Knurled
	P Female Hex Post, Fixed
EMI Panel Gasket	0 No Gasket
	1 Gasket Included <i>(install on mating connector)</i>
Attachment Type <i>(Table 2)</i>	<i>Omit if not required.</i> <i>See Table 2 for attachment types.</i>
Attachment Length	<i>Omit if not required.</i> <i>Length in One Inch Increments</i>
Attachment Ring <i>(Table 3)</i>	<i>Omit if not required</i> <i>See Table 3 for attachment ring options.</i>

