

D-Subminiature

557-071

EMI Banding Backshell

- Solid EMI Backshell, .25" Flange
- Banding Shield Termination
- Qwik-Ty® Strain Relief



T Top Entry



S Side Entry



B 45° Entry




E End Entry

557-071

This accessory fits D-Subminiature M24308 connectors.
Not compatible with Series 28 HiPer-D

One piece, banding, .25 (6.4) flange. 557-071 lightweight aluminum backshell fits M24308 D-Subminiature connectors. Supplied with #4-40 male screwlocks. Terminate cable braid to backshell with banding strap. Optional slot for individual shield pigtailed. Optional Qwik-Ty arm for attaching cable tie (not supplied). Aluminum with stainless steel screwlocks and clips.

TABLE 1
SCREWLOCK OPTIONS

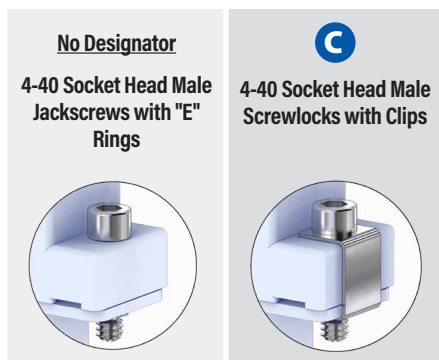

PART NUMBER

Sample PN → **557T071 M 3 31 S C T K**

Base P/N	557B071 B 45° Entry
	557E071 E End Entry
	557S071 S Side Entry
	557T071 T Top Entry
Finish	TZ Tin-Zinc
	MN Mega-Nickel
	JF Cadmium, Yel. Chromate
	M Electroless Nickel
	NF Olive Drab Cadmium
	MT Nickel-PTFE
ZR Black Zinc-Nickel	
Shell Size	1 2 3 4 5 6
Entry Size	Entry Size Entry Dia. Shell Size
	16 .175 (4.4) 1-6
	23 .250 (6.4) 1-6
	30 .312 (7.9) 1-6
	31 .375 (9.5) 1-6
	32 .430 (10.9) 1-6
33 .550 (14.0) 5-6	
Slot	Omit No Slot
	S Slot (in banding area)
Screwlocks (Table 1)	Omit Socket Head Jackscrews with "E" Rings
	C Socket Head Screwlocks with Clips
Qwik-Ty	Omit No Qwik-Ty Strain Relief Arm
	T Qwik-Ty Arm Included
Band	Omit No Band
	B Standard Band Included
	J Slim Standard Band Included

D-SUBMINIATURE ACCESSORIES