

D-Subminiature

557-110 EMI Backshell

- Solid EMI Backshell, .25" Flange
- Cone-and-Ring Shield Termination
- Saddle Clamp Strain Relief



T Top Entry




S Side Entry



E End Entry

CONE-AND-RING SHIELD TERMINATION

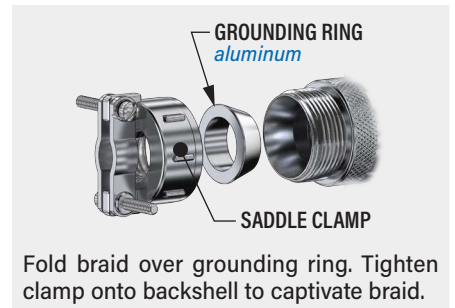

557-110
This accessory fits D-Subminiature M24308 connectors.
Not compatible with Series 28 HiPer-D

One piece, Cone-and-ring shield termination, saddle clamp, .25 (6.4) flange. 557-110 aluminum backshell fits M24308 D-Subminiature connectors. Grounding ring shield termination. Three screwlock options: male socket head, male extended length, or fixed female hex posts. Aluminum with stainless steel screws and clips.

TABLE 1 SCREWLOCK OPTIONS

C	F
4-40 Socket Head Male Screwlocks With Clips	4-40 Female Screwlocks (fixed, non-rotating)
E	
4-40 Extended Length Slotted Male Screwlocks With Clips	

PART NUMBER

Sample PN →	557T110	M	3	F	03	C																							
Base P/N	557E110 E End Entry																												
	557S110 S Side Entry																												
	557T110 T Top Entry																												
Finish	TZ Tin-Zinc																												
	MN Mega-Nickel																												
	JF Cadmium, Yel. Chromate																												
	M Electroless Nickel																												
	NF Olive Drab Cadmium																												
	MT Nickel-PTFE																												
	ZR Black Zinc-Nickel																												
Shell Size	1 2 3 4 5 6																												
Strain Relief	F Saddle Clamp																												
Entry Size	<table border="1"> <thead> <tr> <th>Entry Size</th> <th colspan="2">Cable Range</th> <th>Shell Size</th> </tr> <tr> <th></th> <th>Min</th> <th>Max</th> <th></th> </tr> </thead> <tbody> <tr> <td>02</td> <td>.125 (3.2)</td> <td>.250 (6.4)</td> <td>1-6</td> </tr> <tr> <td>03</td> <td>.250 (6.4)</td> <td>.375 (9.5)</td> <td>1-6</td> </tr> <tr> <td>04</td> <td>.312 (7.9)</td> <td>.500 (12.7)</td> <td>1-6</td> </tr> <tr> <td>05</td> <td>.375 (9.5)</td> <td>.625 (15.9)</td> <td>6</td> </tr> </tbody> </table>	Entry Size	Cable Range		Shell Size		Min	Max		02	.125 (3.2)	.250 (6.4)	1-6	03	.250 (6.4)	.375 (9.5)	1-6	04	.312 (7.9)	.500 (12.7)	1-6	05	.375 (9.5)	.625 (15.9)	6				
Entry Size	Cable Range		Shell Size																										
	Min	Max																											
02	.125 (3.2)	.250 (6.4)	1-6																										
03	.250 (6.4)	.375 (9.5)	1-6																										
04	.312 (7.9)	.500 (12.7)	1-6																										
05	.375 (9.5)	.625 (15.9)	6																										
Screwlocks (Table 1)	Omit #4-40 Tapped Holes																												
	C Socket Head Male Screwlocks																												
	E Extended Slotted Male Screwlock (Profiles S T only)																												
	P Female Screwlocks (fixed)																												

D-SUBMINIATURE ACCESSORIES