

D-Subminiature

557-553 TAG Ring® Backshell

- Solid Backshell, .25" Flange
- TAG Ring® Shield Termination
- Saddle Clamp Strain Relief




T Top Entry



S Side Entry




E End Entry

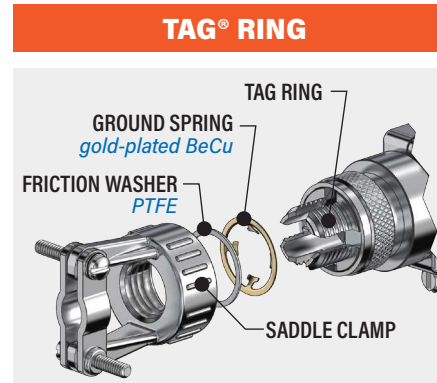

557-553
This accessory fits D-Subminiature M24308 connectors.
Not compatible with Series 28 HiPer-D

TAG Ring shield termination. 557-553 backshell fits M24308 D-Subminiature connectors. TAG ring has slots for individual wire shields. Gold-plated copper alloy spring and PTFE friction washer. Backshell body is aluminum, screws and clips are stainless steel.

**TABLE 1
SCREWLOCK OPTIONS**

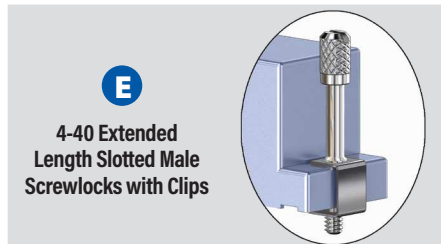

PART NUMBER

Sample PN →	557T553	M	3	F	03	C																				
Base P/N	557E553 E End Entry																									
	557S553 S Side Entry																									
	557T553 T Top Entry																									
Finish	TZ Tin-Zinc																									
	MN Mega-Nickel																									
	JF Cadmium, Yel. Chromate																									
	M Electroless Nickel																									
	NF Olive Drab Cadmium																									
	MT Nickel-PTFE																									
	ZR Black Zinc-Nickel																									
Shell Size	1 2 3 4 5 6																									
Strain Relief	F Saddle Clamp, Short																									
	G Nut																									
	L Saddle Clamp, Long																									
Entry Size	<table border="1"> <thead> <tr> <th>Entry Size</th> <th>Cable Range Min</th> <th>Cable Range Max</th> <th>Shell Size</th> </tr> </thead> <tbody> <tr> <td>02</td> <td>.125 (3.2)</td> <td>.250 (6.4)</td> <td>1-6</td> </tr> <tr> <td>03</td> <td>.250 (6.4)</td> <td>.375 (9.5)</td> <td>1-6</td> </tr> <tr> <td>04</td> <td>.250 (6.4)</td> <td>.438 (11.1)</td> <td>1-6</td> </tr> <tr> <td>05</td> <td>.375 (9.5)</td> <td>.625 (15.9)</td> <td>6</td> </tr> </tbody> </table>	Entry Size	Cable Range Min	Cable Range Max	Shell Size	02	.125 (3.2)	.250 (6.4)	1-6	03	.250 (6.4)	.375 (9.5)	1-6	04	.250 (6.4)	.438 (11.1)	1-6	05	.375 (9.5)	.625 (15.9)	6					
Entry Size	Cable Range Min	Cable Range Max	Shell Size																							
02	.125 (3.2)	.250 (6.4)	1-6																							
03	.250 (6.4)	.375 (9.5)	1-6																							
04	.250 (6.4)	.438 (11.1)	1-6																							
05	.375 (9.5)	.625 (15.9)	6																							
Screwlocks (Table 1)	Omit #4-40 Tapped Holes																									
	C Socket Head Male Screwlocks																									
	E Extended Slotted Male Screwlock (Profiles S T only)																									
	X .125 (3.2) Thru-Holes (screwlocks not included)																									