
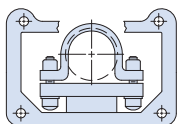


507-249

Saddle Clamp Strain Relief, AS81659

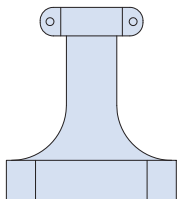


507-249

Saddle-clamp backshell fits AS81659 connectors


Available in three mounting styles. Aluminum with stainless steel screws and washers. Captivated nut is silver-plated SST.

PART NUMBER	
Sample PN →	507-249 M B H
Base P/N	507-249
Finish	M Electroless Nickel JF Cadmium with Yellow Chromate TZ Tin-Zinc NF Olive Drab Cadmium
Mounting	A Angle Mount Left B Back Mount C Angle Mount Right
Mounting Hardware	Omit No Hardware H Hardware Included (4) #2-56 screws and (4) lockwashers

507-249*B BACK MOUNT

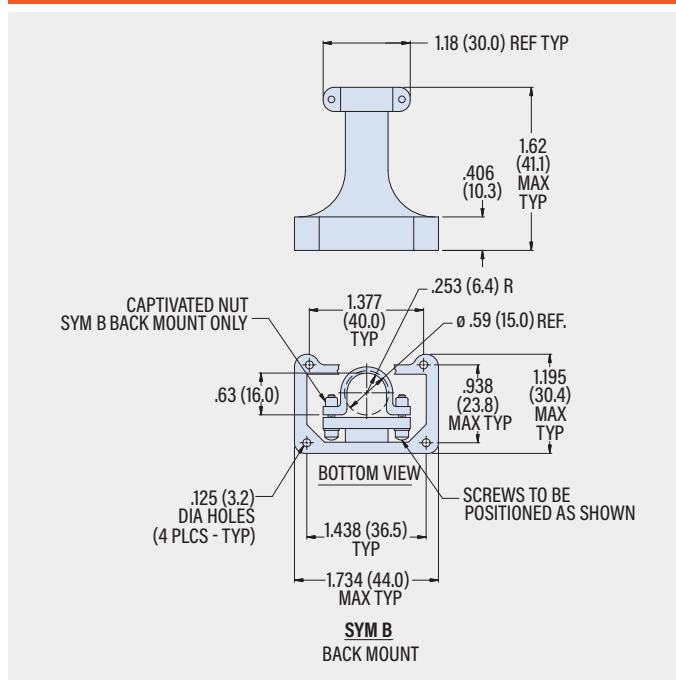

507-249*A AND C ANGLE MOUNT LEFT AND RIGHT

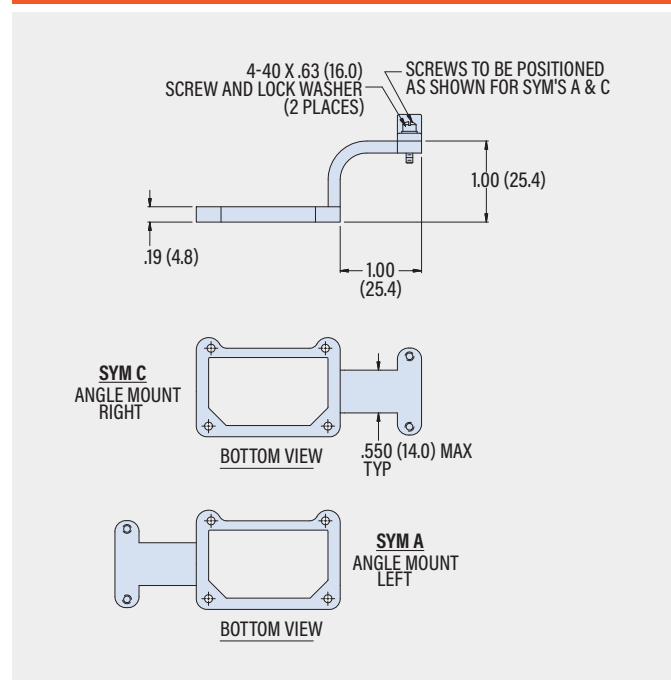

MOUNTING HARDWARE "H" OPTION

