

962-025-086 BLUMARK RF COAX CABLE, CONNECTOR CONTACT, AND MULTI-PORT HOUSING COMPATIBILITY MATRIX



962-025-086

BLUMARK
COAX CABLES RF

- 50 ohm size 086 (.104" jacket diameter, .020" conductor) 40 GHz max. bandwidth low-attenuation cable
- -65 to +150 °C rated operating temperature
- FEP jacket, LPCF dielectric, solid SPC center conductor
- Double-shielded: Tape/braid shield layers with >90 dB shield effectiveness

Size 12 for use with
-086 cable
40 GHz SMPM interface
50 Ohm
Solder termination
Snap-in, rear release
pin and socket coax
contacts, spring-loaded.




Series 23 SuperNine

"Better than QPL" MIL-DTL-38999 Series III



Series 806 RF Mil-Aero

Micro miniature circular IAW D38999

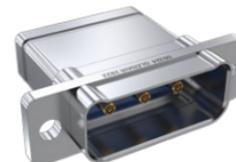

Series 795 RF

High-performance multi-port rectangular

852-099-01 Pin



852-154-01 Socket



852-100-01 Socket

