


Insert Arrangements

SuperNine RF MIL-DTL-38999 Type Size 8 BMB Contact Arrangements

Optimized for Size #8 BMB Contacts

Cable Diameter:
 .240" Max
 .304" Max w/G-Link

Max Frequency:
 18 GHz

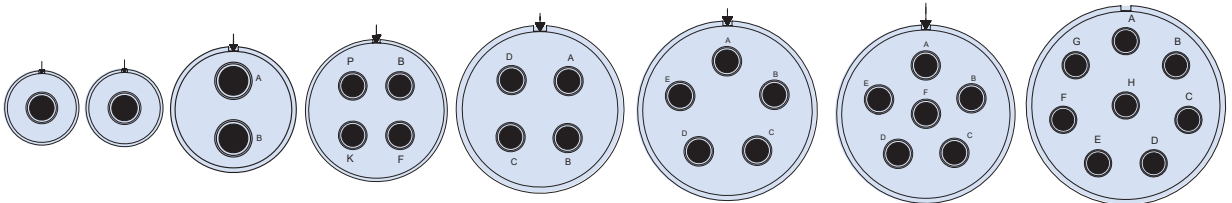


| | | | | | | | | |
|-----------------|---|---|---|--|---|--|--|--|
| Arrangement No. | 9RF5 Shell Sz. 9 1 contact | 11RF1 Shell Sz. 11 1 contact | 17RF75 Shell Sz. 17 2 contacts | 19RF4 Shell Sz. 19 4 contacts | 21RF75 Shell Sz. 21 4 contacts | 23RF5 Shell Sz. 23 5 contacts | 23RF6 Shell Sz. 23 6 contacts | 25RF8 Shell Sz. 25 8 contacts |
|-----------------|---|---|---|--|---|--|--|--|

SuperNine RF MIL-DTL-38999 Type Size 12 SMPM Contact Arrangements

Optimized for Size #12 SMPM Contacts

Cable Diameter:
 .142" Max

Max Frequency:
 40 GHz

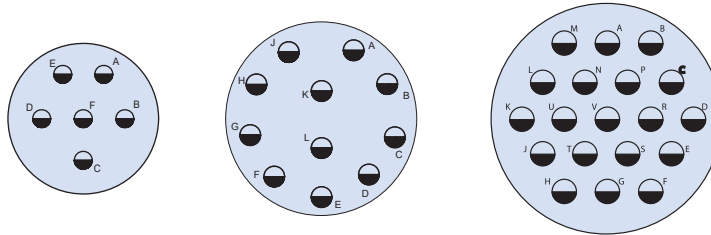


| | | | |
|-----------------|--|---|---|
| Arrangement No. | 17RF6 Shell Sz. 17 6 contacts | 21RF11 Shell Size 21 11 contacts | 25RF19 Shell Size 25 19 contacts |
|-----------------|--|---|---|

SuperNine RF MIL-DTL-38999 Type Size 16 SMPS Contact Arrangements

Optimized for Size #16 SMPS Contacts

Cable Diameter:
 .109" Max

Max Frequency:
 65 GHz

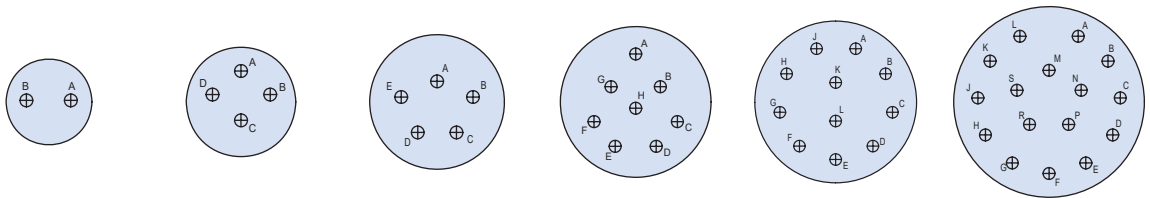


| | | | | | | |
|-----------------|--|--|--|--|--|---|
| Arrangement No. | 11RF2 Shell Sz. 11 2 contacts | 13RF4 Shell Sz. 13 4 contacts | 15RF5 Shell Sz. 15 5 contacts | 17RF8 Shell Sz. 17 8 contacts | 19RF11 Shell Sz. 19 11 contacts | 21RF16 Shell Size 21 16 contacts |
|-----------------|--|--|--|--|--|---|

Optimized for Size #16 SMPS Contacts

Cable Diameter:
 .109" Max

Max Frequency:
 65 GHz

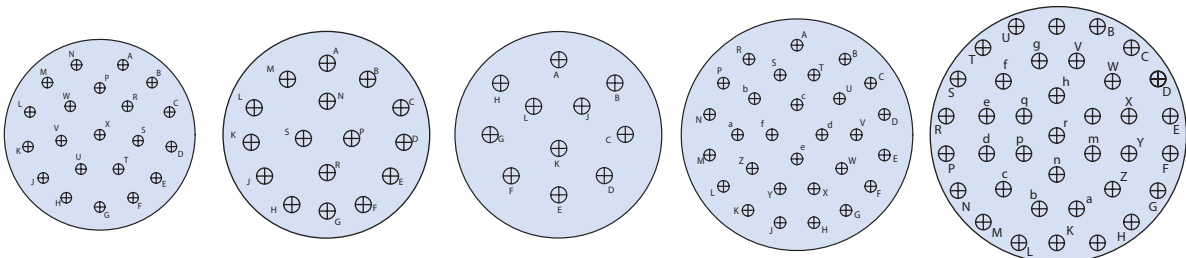

| | | | | | |
|-----------------|---|---|---|---|---|
| Arrangement No. | 23RF21 Shell Size 23 21 contacts | 23RF97 Shell Size 23 16 contacts | 23RF99 Shell Size 23 11 contacts | 25RF29 Shell Size 25 29 contacts | 25RF37 Shell Size 25 37 contacts |
|-----------------|---|---|---|---|---|