
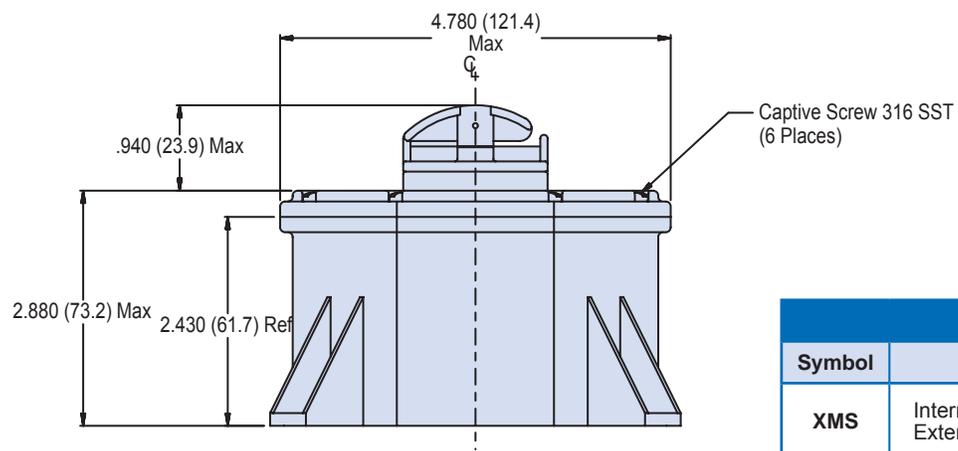
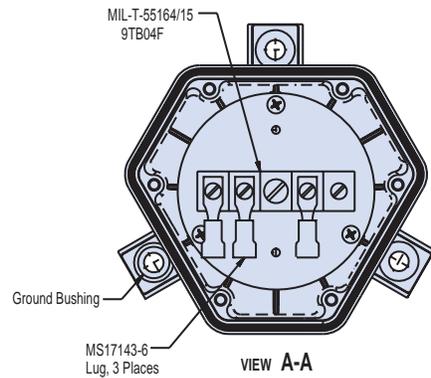



**C Option Supplied with Connector Assembly**  
 See Specific Eng. Dwg.  
 Omit if Not Required

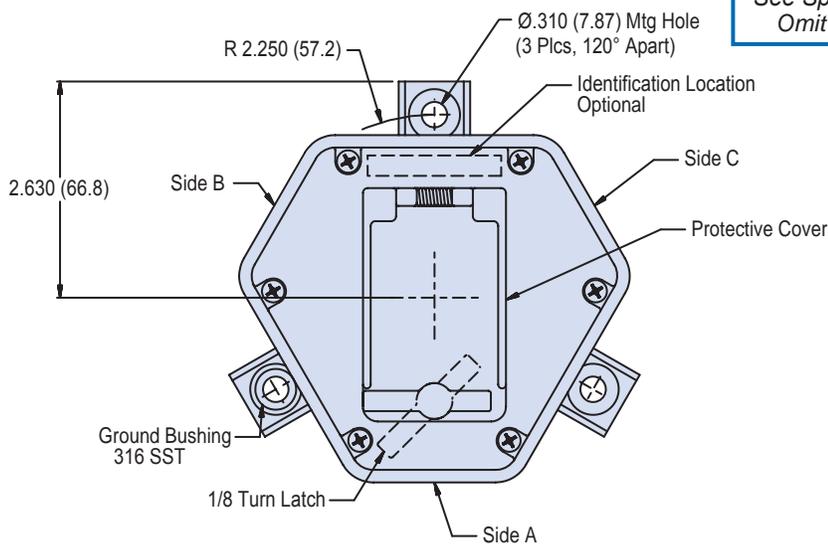

**E**

TABLE I: Finish	
Symbol	Description
XMS	Internal Surfaces - Electroless Nickel Exterior Surfaces - Unplated Light Grey Color
XO	No Plating

**147-033XMS-0003**  
**(NSN: 5940-01-557-2725)**  
**EMI/Environmental Composite Electrical Box**  
**for MS3402 Receptacle Connector • Grounded**

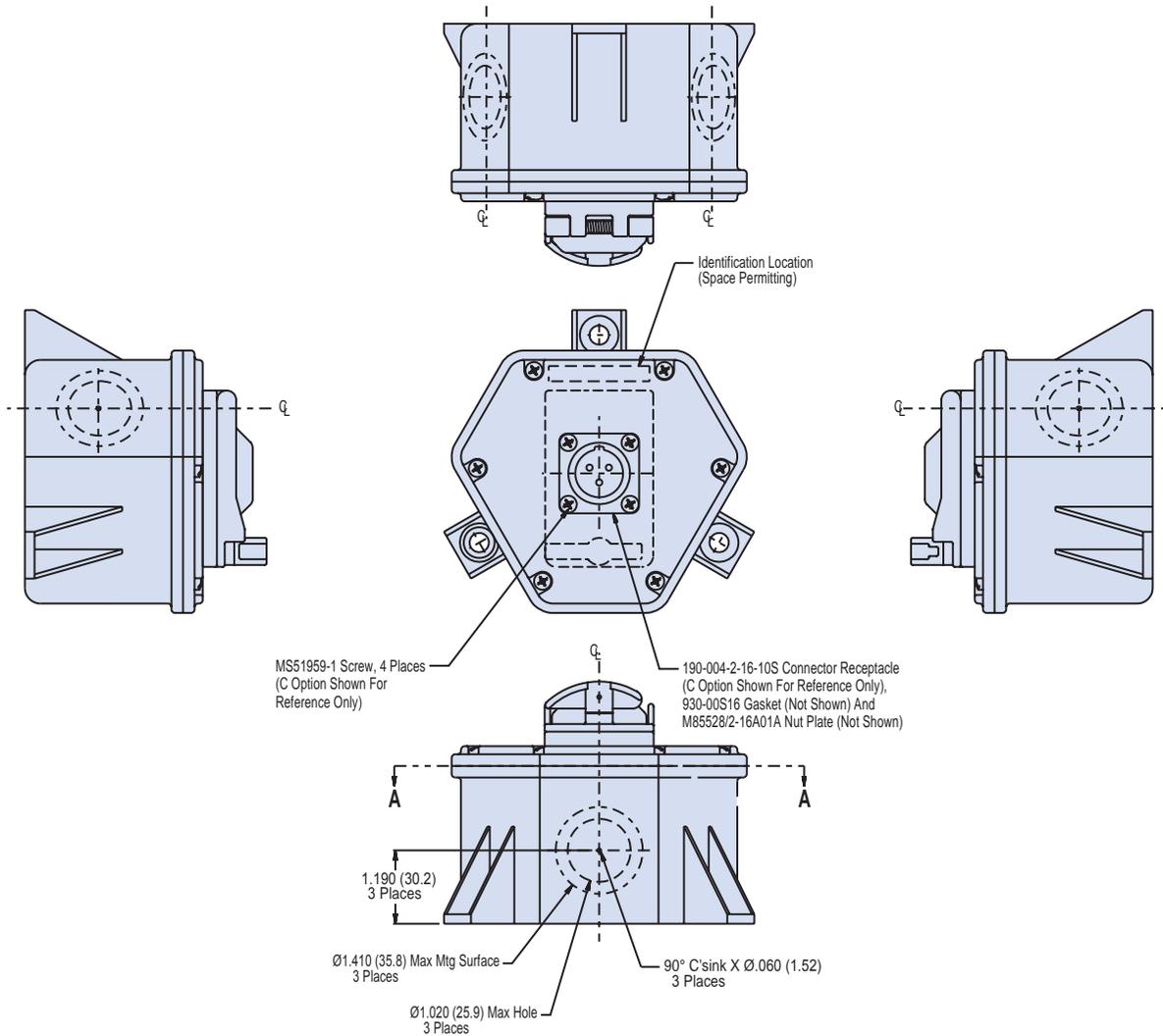

**APPLICATION NOTES**

1. Assembly identified with manufacturer's code identification number (Glenair, part number and date code).
2. Material / Finish:  
 Box, cover - Thermoplastic grey color/see Table I.  
 Hardware - 316 SST/passivate.  
 Seals and gaskets - Silicone/N.A.  
 Mounting Plate - 300 series SST/passivate.
3. Glenair recommended mating connector plug and backshell: 190-004-6-16-10P.
4. Metric dimensions (mm) are indicated in parentheses.