


M28840/13 Protective Receptacle Cover



MIL-DTL
28840

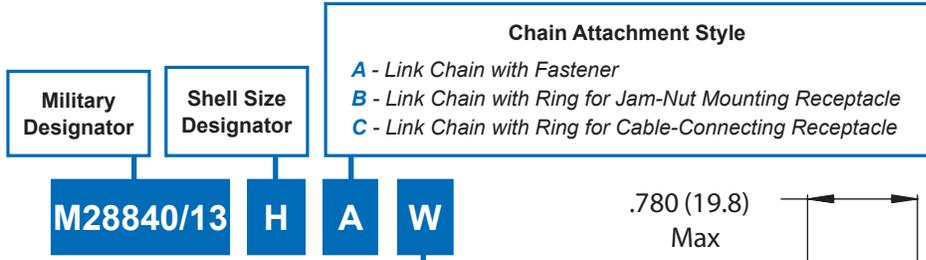


Chain Attachment Style

- A - Link Chain with Fastener
- B - Link Chain with Ring for Jam-Nut Mounting Receptacle
- C - Link Chain with Ring for Cable-Connecting Receptacle

Material and Finish

- W - Aluminum, Cadmium Plate, O.D. over Electroless Nickel
- D - Corrosion Resistant Steel, Cadmium Plate, Black
- L - Aluminum, Tin-Zinc Plate, over Electroless Nickel, Non-Reflective, RoHS

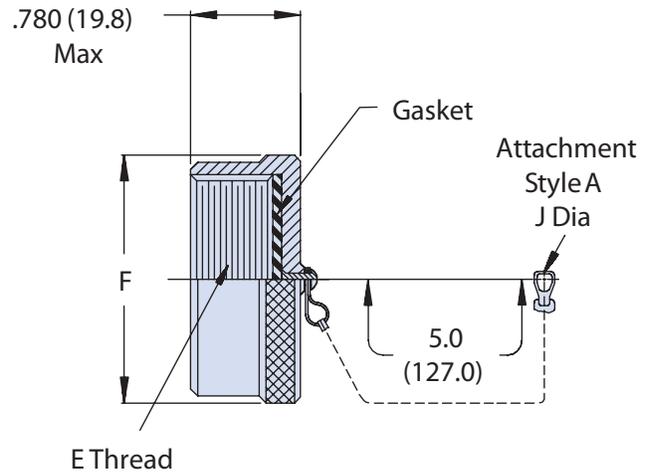

M28840/13 Receptacle Cover

Designator	E Thread Class 2A	F Max. Diameter	H ± .010 (± .25)	J Dia ± .005 (± .13)	G ± .005 (± .13)
A (11)	.750-.1P-.2L-D.S.	1.028 (26.21)	.890 (22.61)	.130 (3.30)	.765 (19.43)
B (13)	.875-.1P-.2L-D.S.	1.141 (23.98)	1.015 (25.78)		.890 (22.61)
C (15)	1.062-.1P-.2L-D.S.	1.263 (32.08)	1.203 (30.56)		1.015 (25.78)
D (17)	1.125-.1P-.2L-D.S.	1.387 (35.23)	1.265 (32.13)		1.140 (28.96)
E (19)	1.312-.1P-.2L-D.S.	1.513 (38.43)	1.453 (36.91)		1.265 (32.13)
F (23)	1.500-.1P-.2L-D.S.	1.703 (43.51)	1.640 (41.66)		1.453 (36.91)
G (25)	1.625-.1P-.2L-D.S.	1.825 (46.35)	1.765 (44.83)	.156 (3.96)	1.577 (40.06)
H (29)	1.812-.1P-.2L-D.S.	2.143 (54.43)	1.953 (49.61)		1.890 (48.01)
J (33)	2.000-.1P-.2L-D.S.	2.329 (59.16)	2.140 (54.36)		.193 (4.90)

Table I					
Designator	Desc	Contact Size	Crimp Barrel Size	Wire size	Contact PN
P	Pin	20	22	22-26AWG	M39029/83-450
S	Socket	20	22	22-26AWG	M39029/83-452
D	Pin	20	28	28-30AWG	M39029/83-451
E	Socket	20	28	28-30AWG	M39029/83-453
F	Pin	20	20	20-24AWG	M39029/83-508
G	Socket	20	20	20-24AWG	M39029/83-509