

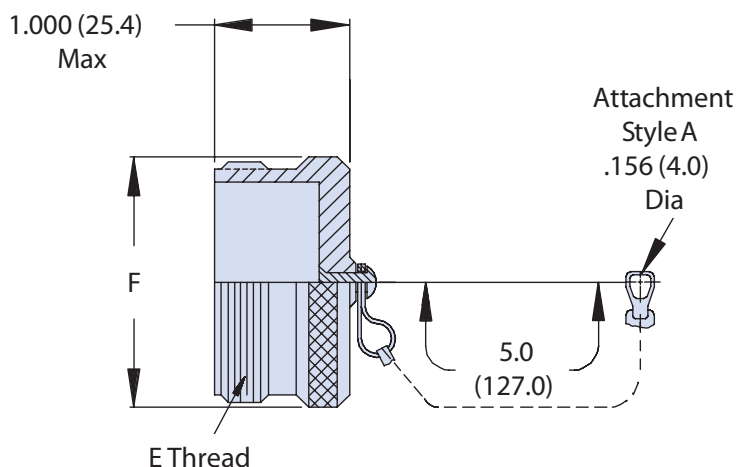
M28840/15 Protective Plug Cover

**Military
Designator**
**Shell Size
Designator**
Material and Finish

W - Aluminum, Cadmium Plate, O.D. over Electroless Nickel
D - Corrosion Resistant Steel, Cadmium Plate, Black
L - Aluminum, Tin-Zinc Plate, over Electroless Nickel,
 Non-Reflective, RoHS

M28840/15
H
A
W
Chain Attachment Style

A - Link Chain with Fastener
B - Link Chain with Ring for Jam-Nut Mounting Receptacle


M28840/15 Plug Cover

Designator	E Thread Class 2B	F Max. Diameter
A (11)	.750-1P-.2L-DS	1.028 (26.21)
B (13)	.875-1P-.2L-DS	1.141 (28.98)
C (15)	1.062-1P-.2L-DS	1.263 (32.08)
D (17)	1.125-1P-.2L-DS	1.387 (35.23)
E (19)	1.312-1P-.2L-DS	1.108 (28.14)
F (23)	1.500-1P-.2L-DS	1.293 (32.84)
G (25)	1.625-1P-.2L-DS	1.454 (36.93)
H (29)	1.812-1P-.2L-DS	1.620 (41.15)
J (33)	2.000-1P-.2L-DS	1.812 (46.02)