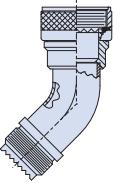
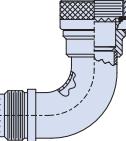
 
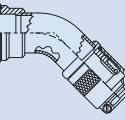
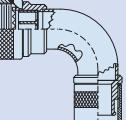
 
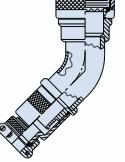
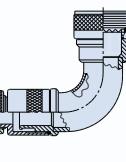
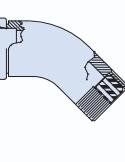
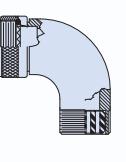


## Backshell Selection Guide

Backshells listed here are specially designed to fit over size 8 data contacts and their grommet followers and accommodate the appropriate bend radius for the cables they are used with.

Adapter Code **H**

This accessory fits these connectors:  
MIL-DTL-38999 Series III and Series IV

High Speed Contact Backshell Options							
Series	EMI	Environmental	Strain Relief	Straight	45°	90°	Description
320H*030	Backshell Dependent	Backshell Dependent	Backshell Dependent				<b>Extender Adapter</b> Transition from oversized contact package to standard backshell (contact Glenair to confirm backshell compatibility)
4470H*1130	Banding Porch	No	Saddle Bar				<b>Band In A Can</b> Advised for overbraid w/ or w/o individual shield terminations requiring medium duty strain relief
443H*042	Banding Porch	O-Ring Gland (Splash Proof)	Saddle Bar				<b>EMI/RFI Banding Strain Relief Environmental</b> Advised for environmental overbraid w/ or w/o individual shield terminations requiring medium duty strain relief
620H*090	No	No	Saddle Bar		N/A	N/A	<b>Extended Strain Relief</b>
377N*119	Optional Banding Porch	Sealing Gland	Yes				<b>Environmental Sealing Backshell</b>
* - Orientation S - Straight M - 45 Degrees N - 90 Degrees							