


8572-0013 Threaded Coupling Patch Cord, SuperFly-to-USB 3.0




Standard USB connectors. Commercial grade. Save assembly time and cost with pre-wired SuperFly Datalink "Blue" Octaxial assemblies for SuperSpeed USB. Available with Type A, Type B or μ B interfaces, these cordsets have a SuperFly connector on one end and a standard USB 3.0 connector on the other end.

- ### SuperFly Connector Construction
- **Shell, coupling nut, backshell:** aluminum or SST
 - **Insulators:** high-grade rigid dielectric
 - **Contacts:** copper alloy, 50 microinches gold over nickel plating
 - **Grommet:** fluorosilicone
 - **O-rings:** fluorosilicone
 - **Shield sleeve, ferrule:** copper alloy, nickel plated
 - **Cable:** commercial-grade shielded USB 3.0 with black LSZH jacket

- ### Specifications
- **Operating temp.:** 0° to +80°C
 - **Impedance:** 90 ohms
 - **DWV:** 100 Vrms unmatd
 - **Current Rating:** 1.5 A
 - **IR:** 100 M Ω min.

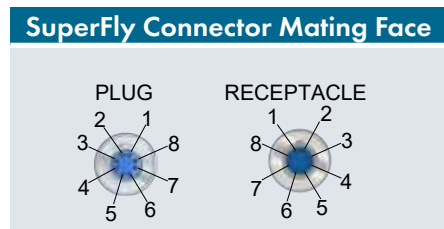

How To Order SuperFly to USB 3.0 Plug Patchcord				
Sample Part Number	8572-0013	- M	-01	-24
Product	8572-0013 = Pre-wired SuperFly Connector to standard USB 3.0 connector. Double-ended Cordset			
Shell Finish	M = Electroless Nickel (aluminum shell) MT = Nickel-PTFE (aluminum shell) ZR = Black Zinc-Nickel (aluminum shell) Z2 = Gold (aluminum shell) ZMT = Nickel-PTFE (stainless steel shell)			
Order Code Connector Types	01 = Plug connector to USB 3.0 Type A plug 02 = Receptacle connector to USB 3.0 Type A receptacle 03 = Receptacle connector to USB 3.0 Type B plug 04 = Receptacle connector to USB 3.0 Type μ B plug			
Overall Length	Length in Inches (12 inch minimum)			

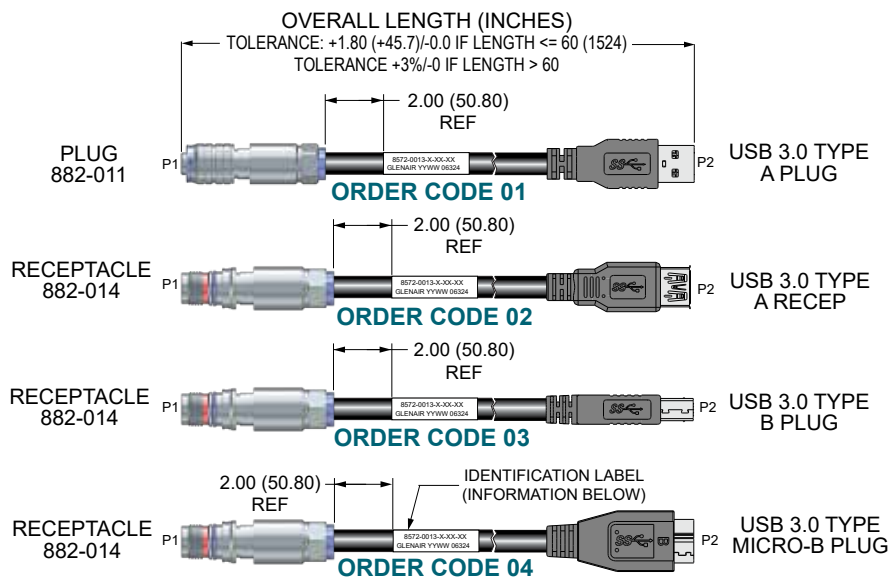

LABEL INFORMATION
 8572-0013-X-XX-XX
 GLENAIR YYWW 06324