



RJ45 CAT 5E ETHERNET

MIL-DTL-38999 Series III Type Connectors



CAT 5e cable assemblies

B




**2330-0003 Glenair SuperNine RJ45 CAT 5e cable jumpers, SuperSeal to standard RJ45**

SuperSeal RJ45 connectors are IP67 open face rated and IP68 in the mated condition for complete protection in harsh environments. SuperSeal connector styles include plug, wall mount and jam-nut receptacles. Wall mount receptacles are available with slotted holes, round holes and metric clinch nuts. All SuperSeal shells offer inline shielding and receptacle shells offer optional shell grounding. Any shell can be ordered with straight or right angle cable exit. RJ45 jack can be ordered in 1 of 4 available orientations to provide further security against mis-mating and accommodate existing RJ45 orientations. RJ45 connector end may be ordered as plug, jack or with flying leads in straight or right angle configurations. Maximum overall length is 100 feet. Consult factory for ordering information.

**AVAILABLE INTERFACE OPTIONS**




**Plug**

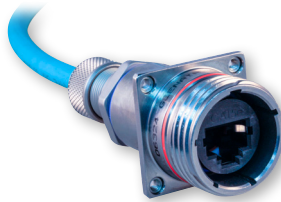

**Wall mount receptacle with metric clinch nuts**



**Wall Mount Receptacle with round holes**

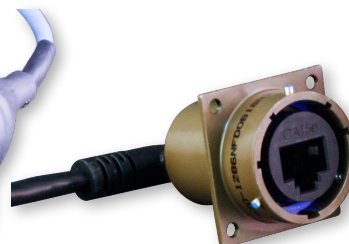

**Wall Mount Receptacle with round holes**



**Jam-nut mount Receptacle**

**CAT 5E PLUG OPTIONS**



**CAT 5e, Straight**



**CAT 5e, Straight**



**CAT 5e, 45°**

**RJ45 ORIENTATION OPTIONS**

