



USB 2.0 TYPE A

Series 801, 804 and 805 Mighty Mouse



801-340 Coupler with USB Male-to-Female (Plug) or Female-to-Female (Receptacle)


How To Order									
Sample Part Number	801-340	-	NF	07	-16	2	A	A	H
Series	801-340								
Rear Accessory Option	-- = Accessory Thread and Teeth S = Integrated Banding Platform B = Integrated Boot Adaptor								
Material and Finish ¹	NF = Aluminum/Cadmium, Olive Drab M = Aluminum/Electroless Nickel MT = Aluminum/Nickel PTFE ZNU = Aluminum/Black Zinc Nickel								
Shell Style ¹	01 = In Line Receptacle 02 = Front or Rear Panel Mount Square Flange Receptacle 07 = Rear Panel Mount Jam Nut Receptacle 26 = Plug								
Shell Size	16 = Shell Size 16								
USB Performance	2 = USB 2.0								
USB Type	A = Type A								
Alternate Key Positions ¹	A, B, C, D, E, F								
USB Orientation	H = Horizontal V = Vertical								

Series 801 Double Start

NOTES


1. See Section A for recommended panel cutout dimensions, additional finishes and alternate keyway positions.
2. Meets IP67 sealing requirement in unmated condition

USB 2.0 ORIENTATION OPTIONS

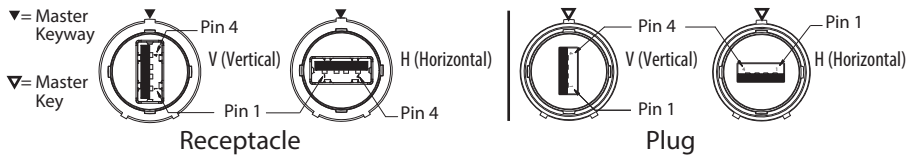

Dimensions											
Size Shell	Ø A	B Flat	C Threads	D Threads	Ø E	F Sq	G Bsc	Ø J	K Flat	M Threads	Ø N
16	1.040 (26.42)	1.010 (25.65)	1.0000-.1P-.2L-DS-2A	.9375-20 UNEF-2A	1.625 (41.28)	1.219 (30.96)	.981 (24.92)	1.264 (32.11)	1.230 (31.24)	1.0625-20 UN-2A	1.230 (31.24)

SHELL STYLE 01 INLINE RECEPTACLE

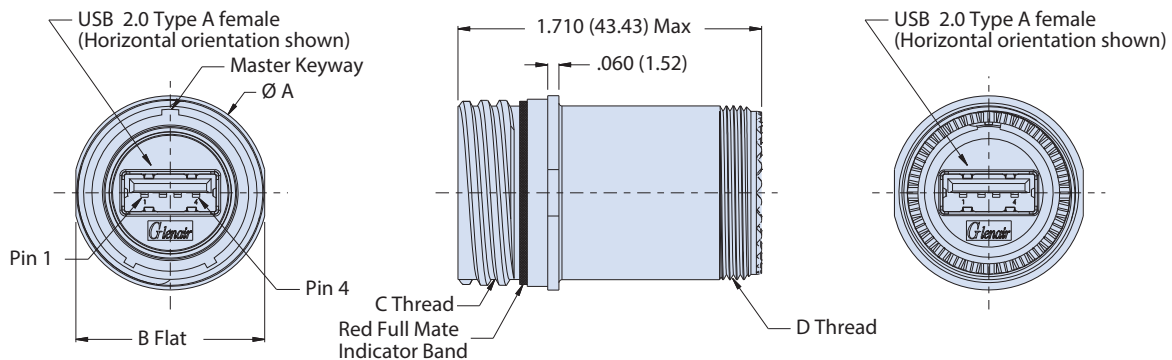




USB 2.0 TYPE A
Series 801, 804 and 805 Mighty Mouse
 801-340 Coupler with USB Male-to-Female (Plug) or
 Female-to-Female (Receptacle)




Series 801 Double Start


SHELL STYLE 02 FRONT OR REAR SQUARE FLANGE RECEPTACLE

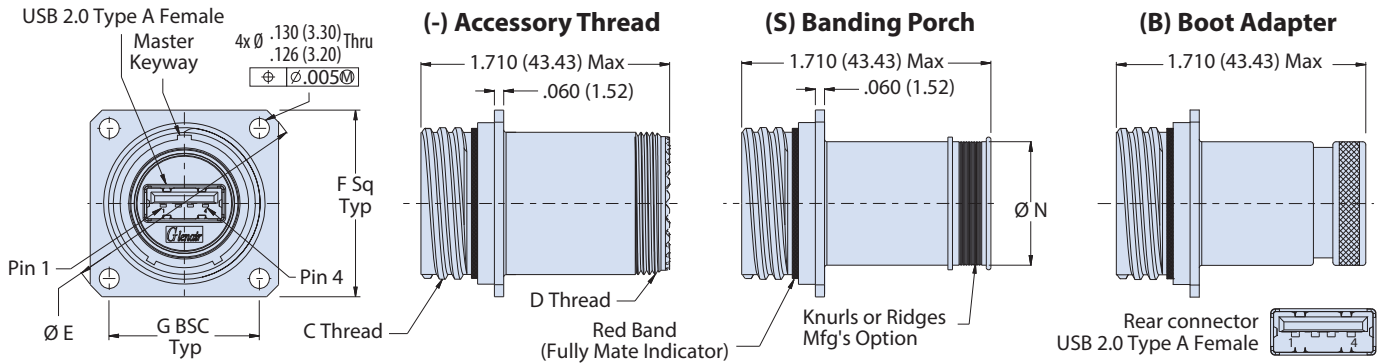

SHELL STYLE 07 REAR PANEL MOUNT JAM NUT RECEPTACLE

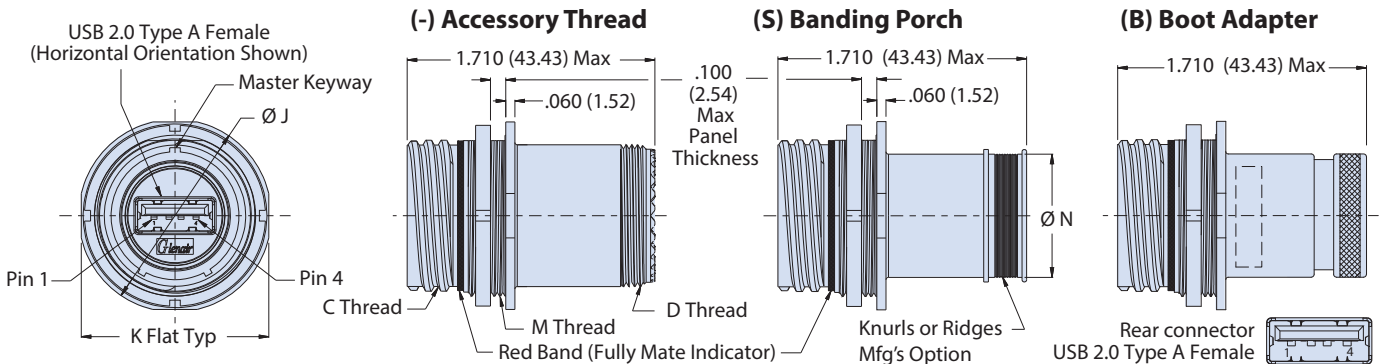

SHELL STYLE 26 PLUG

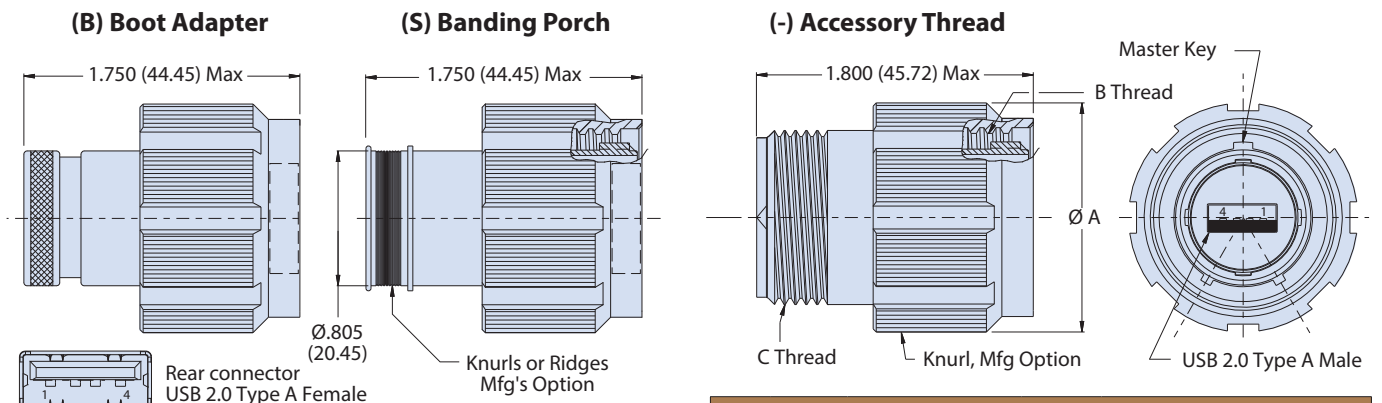

Plug Dimensions			
Shell Size	Ø A	B Threads	C Threads
16	1.340 (34.04)	1.0000-1P-2L-2B	.9375-20 UNEF-2A

USB 2.0 Wiring				
Pin	Name	Cable Color(USB)	Desc.	Recommended Wire Size (AWG)
1	(V Bus)	Red	+5V	22
2	(D-)	White	Data -	28
3	(D+)	Green	Data +	28
4	(GND)	Black	Ground	22