




DEEP WATER SeaKing™ Fiber Optic



SeaKing™ BCR or FCR to commercial fiber optic pigtail assembly for I/O-to-board module applications

SeaKing Fiber - How To Order	
Sample Part Number	FA09649 -B F Z1 -0F8 N -XXXX C
Basic Number	SeaKing Fiber Optic receptacle breakout assembly
J1 Option	B = BCR F = FCR
P1 Option	C = SC Leads F = FC Leads L = LC Leads N = None S = ST Leads
Shell Material	TC = Titanium Z1 = 316 Stainless Steel
Insert Arrangement	See Table I & II Insert Body Material: 316 SST
Key Arrangement	A, B, or C; N = normal,
Length	In inches (See Standard Tolerance Table)
Pressure Cap Option	C = Provided With Pressure Caps N = No Pressure Caps

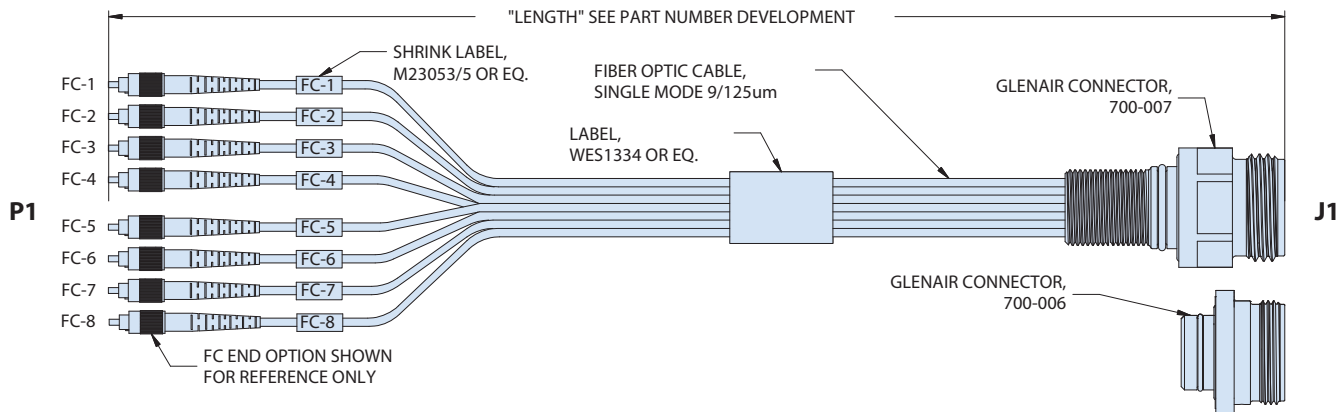

NOTES

- Optical performance:
Insertion loss shall be <1.0dB when measured @ 1310nm wavelength. Insertion loss can be measured at 1550nm upon customer request.
- Unit pack: 1 EA. In a bag and/or cardboard box, label package IAW illustration.
- Mark reference designators as shown. Reference designator number shall match the contact number.
- See drawing 700-006 and 700-007 for connector dimensions, materials, and finishes.
- Wiring for each arrangement is one to one.

END 2 COMMERCIAL FIBER OPTIC CONNECTOR OPTIONS

