



 


DEEP WATER SeaKing™ Fiber Optic






Fiber optic insert arrangements

Fiber Only

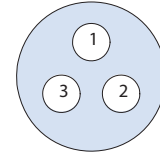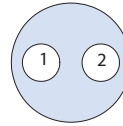





Shell Size	E	K	L
Insert Arrangement	EF1	KF2	LF3
No. of Contacts	1 FO	2 FO	3 FO

Fiber Only

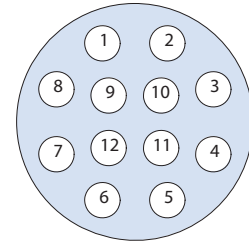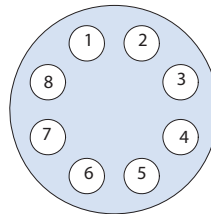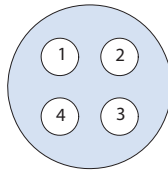



Shell Size	M	O	P
Insert Arrangement	MF4	OF8	PF12
No. of Contacts	4 FO	8 FO	12 FO

Copper/Fiber

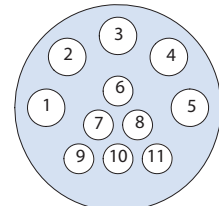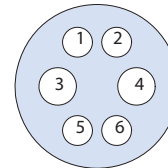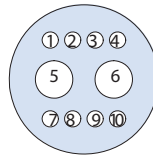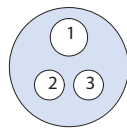

Shell Size	K	L	M	O
Insert Arrangement	KH12	LH28	MH24	OH56
No. of Fiber Contacts	1 FO	2 FO	2 FO	5 FO
No. of Copper Contacts	2 #16	8 #22	4 #16	6 #16

Copper/Fiber

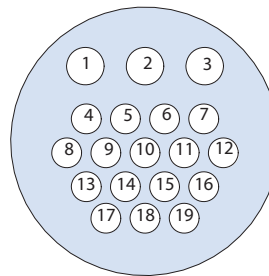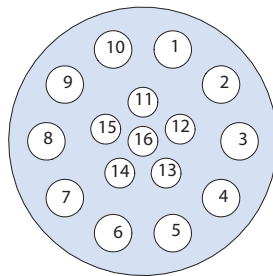

Shell Size	Q	Q
Insert Arrangement	QH106	QH316
No. of Fiber Contacts	10 FO	3 FO
No. of Copper Contacts	6 #16	16 #16

Contact Specifications		
Contact Size	#22	#16
Amps	3	10
Wire Gage Accommodation	22	16

All contact arrangements are rated for 600 volts.

Contact arrangements are shown as face view of receptacle insert. Contact arrangements of plug inserts are reverse.