





SERIES 70 10K PSI / 700 BAR / 7000 M

SeaKing™ High-Pressure Subsea Connectors, Cables, and PBOF Assemblies

709-220 PEEK Coupling Nut Assembly for Temporary Field Repair (CCP)



SeaKing CCP - How To Order		
Sample Part Number	709-220	-P
Product Series	709-220 = SeaKing PEEK Coupling Nut Assembly for Temporary Field Repair	
Fit Connector Shell Size	See Dimensions Table	

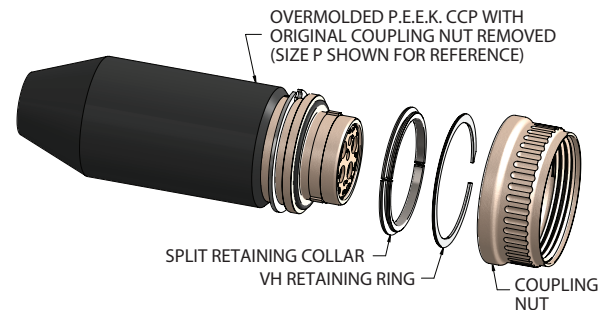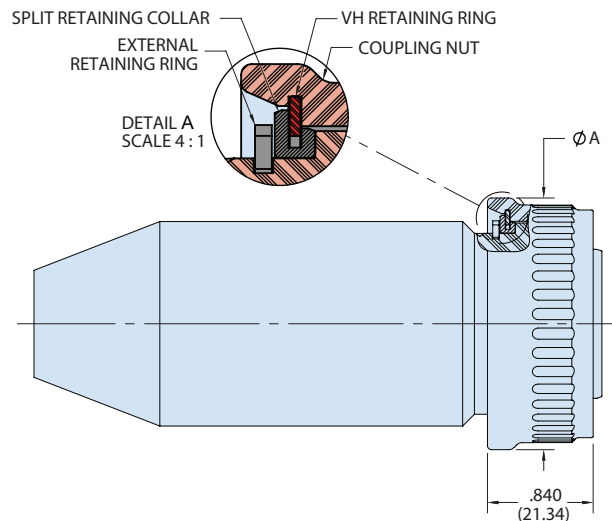

NOTES

Used for emergency, temporary field repairs only when original coupling nut has been damaged. Not intended for permanent, deployed service. Completely remove damaged original coupling nut prior to installation. Fits seaKing P.E.E.K. CCP connectors / cable assemblies. Package 1 ea. Items together in heat sealed poly bag, and label per standard practices.

MATERIAL COMPOSITION:

Coupling nut: glass reinforced P.E.E.K.
Split retaining collar: titanium, Gr. 5 (Ti-6AL-4V)
Retaining ring: elgiloy

Dimensions						
SeaKing Size	$\varnothing A$		Temp. Field Repair Coupling Nut	Split Retaining Collar	Internal Retaining Ring	Mating Torque (Ft-Lbs)
	In.	mm				
E	1.13	28.70	709-405-E	709-406-E	VH-81-LGY	8
G	1.25	31.75	709-405-G	709-406-G	VH-93-LGY	10
K	1.38	35.05	709-405-K	709-406-K	VH-106-LGY	12
L	1.50	38.10	709-405-L	709-406-L	VH-118-LGY	12
M	1.63	41.40	709-405-M	709-406-M	VH-131-LGY	12
O	1.88	47.75	709-405-O	709-406-O	VH-162-LGY	15
P	2.00	50.80	709-405-P	709-406-P	VH-175-LGY	15
Q	2.13	54.10	709-405-Q	709-406-Q	VH-187-LGY	15
R	2.25	57.15	709-405-R	709-406-R	VH-200-LGY	15

SUBSEA/DEEPWATER: SEAKING™

