

968-001


27500 Type With Specialty Braid

NOTES

1. Consult factory for cable diameters exceeding 0.375 inches.
2. Number of conductors is dependent on maximum cable diameter.

Capabilities. Consult factory for capabilities.

HOW TO ORDER							
Sample Part Number	968-001	-	22	TE	2	AR	14
Basic Part Number	968-001						
Identification Method	See Table IV						
Conductor Size	See Table I						
Basic Wire Description	See Table I						
Number Of Conductors	See Table I						
Shield Description	See Table II						
Jacket Type	See Table III						

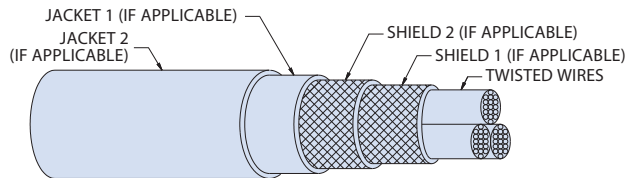

CABLE CONSTRUCTION EXAMPLE

Single Jacket Code	Double Jacket Code	Jacket Material Description
00	00	No Jacket
05	55	Extruded FEP, Clear
09	59	Extruded FEP, White
10	60	Extruded PVDF, Clear
14	64	Extruded ETFE, White
15	65	Extruded ETFE, Clear
20	70	Extruded PFA, White
21	71	Extruded PFA, Clear

Code	Wire Type	AWG	# Of Conductors
TE	M22759/16 or GS22759-16	8 to 24	1,2,3,4,5
TF	M22759/17 or GS22759-17	20 to 26	1,2,3,4,5
TG	M22759/18 or GS22759-18	10 to 26	1,2,3,4,5
TH	M22759/19 or GS22759-19	20 to 26	1,2,3,4,5
SB	M22759/32 or GS22759-32	12 to 30	1,2,3,4,5
SC	M22759/33 or GS22759-33	20 to 30	1,2,3,4,5
SD	M22759/34 or GS22759-34	8 to 24	1,2,3,4,5
SE	M22759/35 or GS22759-35	20 to 26	1,2,3,4,5
SM	M22759/41 or GS22759-41	8 to 26	1,2,3,4,5
SN	M22759/42 or GS22759-42	20 to 26	1,2,3,4,5
SP	M22759/43 or GS22759-43	8 to 26	1,2,3,4,5
SR	M22759/44 or GS22759-44	12 to 28	1,2,3,4,5
SS	M22759/45 or GS22759-45	12 to 28	1,2,3,4,5
ST	M22759/46 or GS22759-46	20 to 28	1,2,3,4,5

Code	Description
-	85% Coverage, White Wire With Colored Stripes
C	90% Coverage, White Wire With Colored Stripes

Single Shield Code	Double Shield Code	Shield Description
AM	AS	AmberStrand®, Round
AR	AL	ArmorLite™, Round
AC	AF	ArmorLite™ CF, Round
U	U	Unshielded